


L34010




Y/T splitter

SPLITTER,M12 MALE,TO 2 M12 FEM

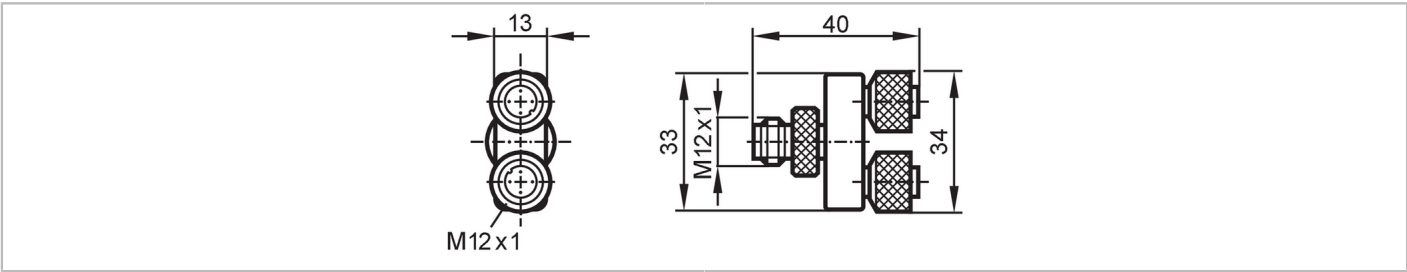

Application		
Special feature		Free from silicone; gold-plated contacts
Application		Industrial applications
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 30 AC / < 36 DC
Max. current load per module/slot	[A]	4
Max. current load total	[A]	4
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Weight	[g]	22.68
Material		housing: PUR
Material nut		brass, nickel-plated / brass, PTFE coated
Number of ports splitter box		2
Connector type		M12
Remarks		
Remarks		output A nut PTFE-coated (black) output B nut nickel-plated
Pack quantity		1 pcs.
Electrical connection - plug		

 Connector: 1 x M12; coding: A; Contacts: 5, gold-plated; Locking: brass, nickel-plated




L34010



Y/T splitter

SPLITTER,M12 MALE,TO 2 M12 FEM

Connection

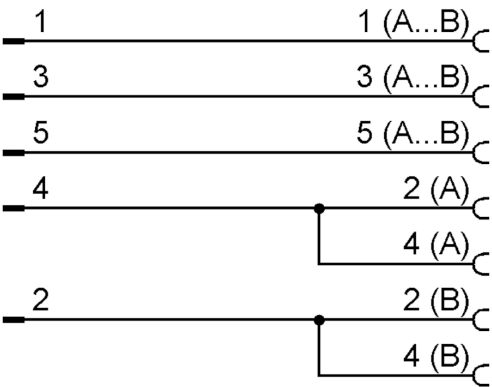

Electrical connection - Socket

Connector: 2 x M12; coding: A; Contacts: 5, gold-plated; Locking: brass, PTFE coated

