


E11248



Connecting cable with socket

ADOAA050MSS0005H04

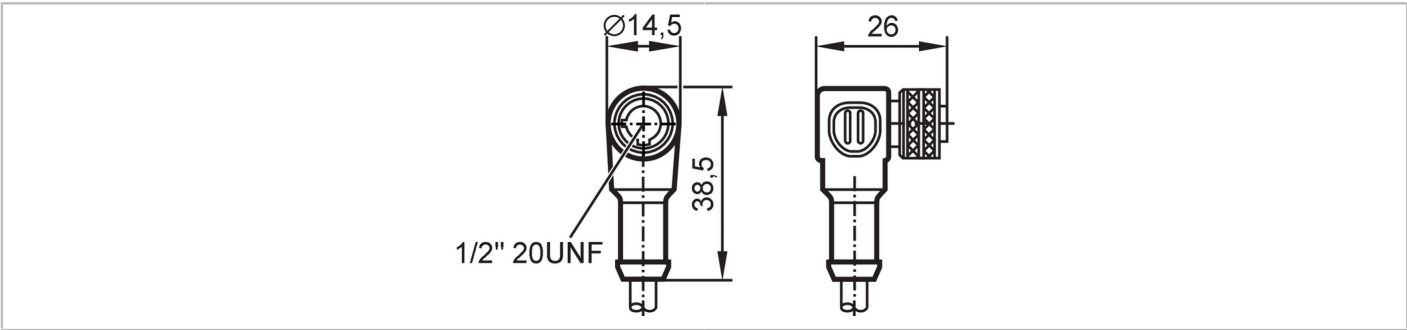

Application

Special feature	Halogen-free
Application	Industrial applications / factory automation

Electrical data

Operating voltage	[V]	< 300 AC
-------------------	-----	----------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Weight	[g]	165.2
Moulded-body material		TPU
Material nut		brass, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection


Cable: 5 m, PUR, Halogen-free, black, Ø 4.7 mm; 4 x 0.34 mm² (43 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x 1/2", angled; coding: C; Contacts: 4; Moulded body: TPU; Locking: brass, nickel-plated



Connection

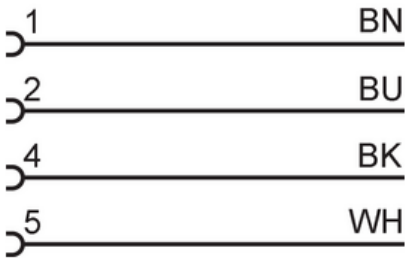

Core colours :
BK = black
BN = brown
BU = blue
WH = white