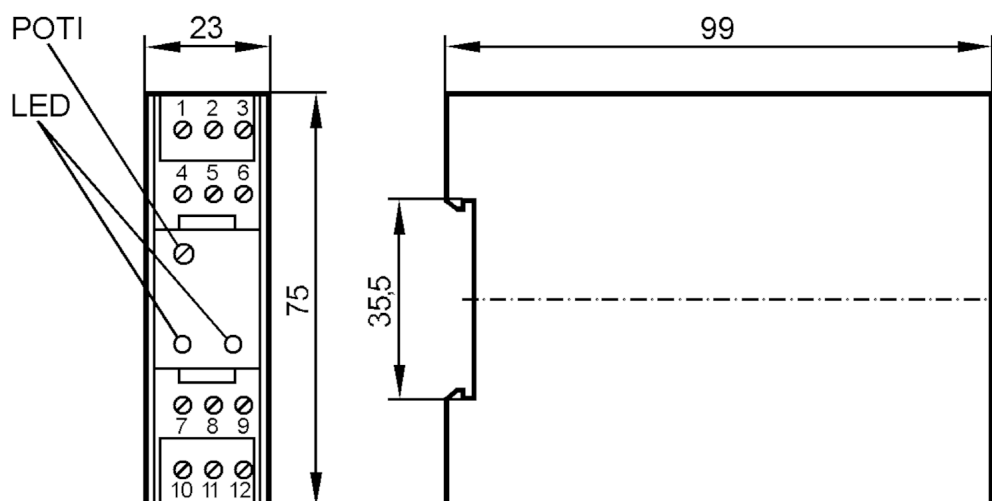


Article no longer available - archive entry

**Electrical data**

Operating voltage	[V]	10...55 DC
Current consumption	[mA]	40; (24 V)

Outputs

Total number of outputs	1
Electrical design	PNP/NPN
Output function	light-on/dark-on mode; (parameterisable)
Switching frequency DC [Hz]	100

Operating conditions

Ambient temperature	[°C]	0...70
Protection		IP 40
Protection rating terminals		IP 20

Mechanical data

Weight	[g]	135.5
Housing		rectangular
Type of mounting		mounting on DIN rail; (TH35 (EN 60715))
Dimensions	[mm]	75 x 23 x 99
Materials		housing: PBT

Displays / operating elements

Display	switching status	1 x LED, red
	setting aid	1 x LED, yellow




Remarks

Pack quantity 1 pcs.

Electrical connection

terminals: 12 x ...2.5 mm²

Connection

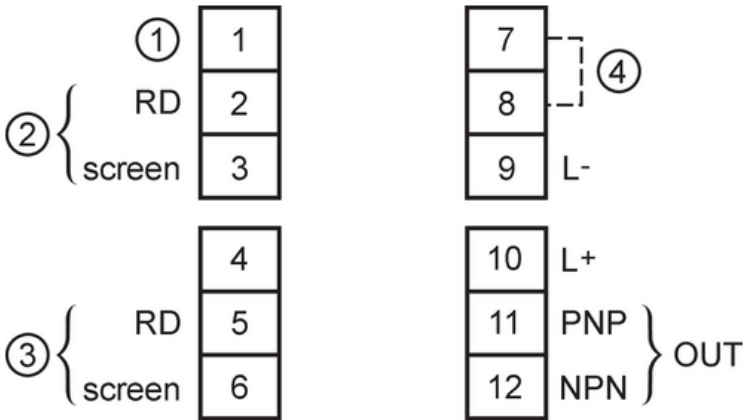

1 blocking signal
2 transmitter
3 receiver
4 Output function
OUT transistor outputs