


E12490



Ethernet connection cable

VSTGN040ZDS00,5L04STGP040--S

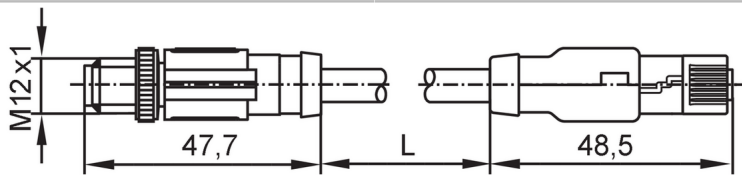

Application		
Special feature		gold-plated contacts; screened cable
Design		Ethernet cable, D-coded
Application		Industrial applications; Patch cable
Electrical data		
Operating voltage	[V]	48 AC / 60 DC
Protection class		III
Max. current load total	[A]	1
Operating conditions		
Ambient temperature	[°C]	-25...70
Protection		IP 65; IP 67; (M12 plug / RJ45 plug: IP 20)
Mechanical data		
Weight	[g]	73.1
Molded-body material		TPU (urethane) / PA
Material nut		diecast zinc, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection - plug M12		
Connector: 1 x M12, straight; coding: D; Contacts: 4, gold-plated; Moulded body: TPU (urethane), black; Locking: diecast zinc, nickel-plated; Tightening torque: 0.4 Nm		

E12490




Ethernet connection cable

VSTGN040ZDS00,5L04STGP040--S

Electrical connection

Cable: 0.5 m, PVC, green, Ø 6.5 mm, screened; PROFINET; 4 x 0.34 mm² (7 x Ø 0.25 mm)

Connection

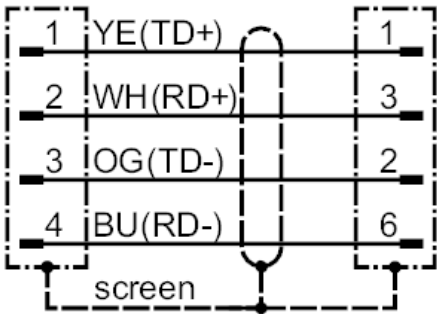

Electrical connection - plug RJ45

Connector: 1 x RJ45, straight; Contacts: 8, gold-plated; Moulded body: PA

