


E11550

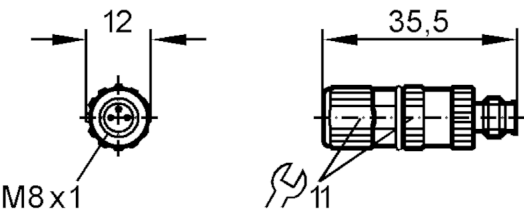

Wirable plug

SSTGF030MSSFPKG



Application		
Special feature		gold-plated contacts
Application		Industrial applications
Electrical data		
Operating voltage	[V]	< 50 AC / < 75 DC
Protection class		III
Max. current load total	[A]	4
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 68
Mechanical data		
Weight	[g]	14.8
Material		Core insulation: PVC / TPE
Molded-body material		PA
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection		
insulation displacement technology: 0.14...0.38 mm ² ; Core insulation: PVC / TPE; (Ø 1.0...1.6 mm); Cable sheath: Ø 3...5 mm		
Electrical connection - plug		
Connector: 1 x M8, straight; coding: A; Contacts: 3, gold-plated; Moulded body: PA; Locking: brass, nickel-plated		

E11550



Wirable plug

SSTGF030MSSFPKG

Connection	
	1
	3
	4