




Multifunction display for monitoring analogue standard signals

DISPLAY/AX460/ANALOG/AC/DC

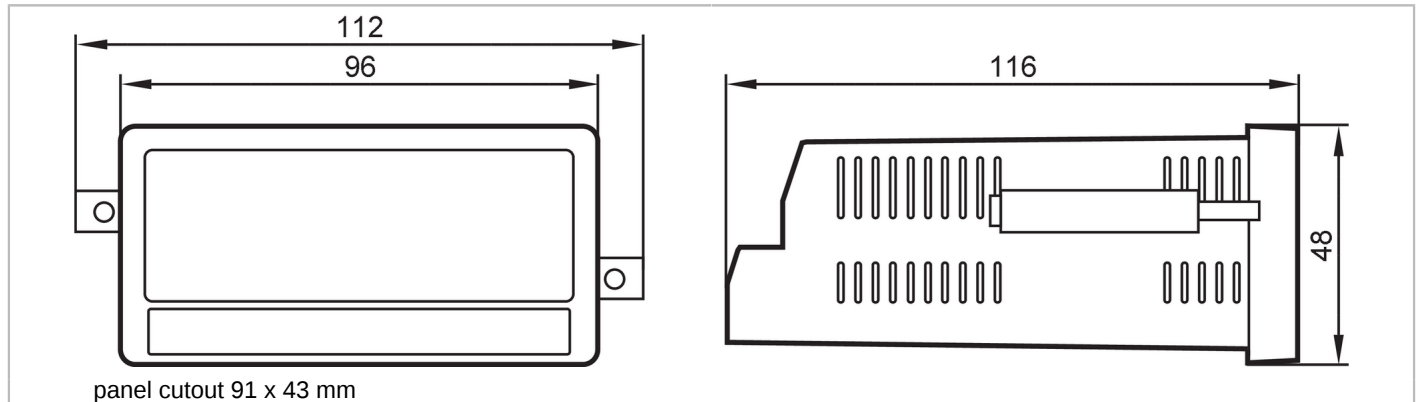

Product characteristics		
Housing		rectangular
Dimensions	[mm]	48 x 112 x 116
Application		
Application		displaying and monitoring analogue signals; e.g. pressure sensors, temperature sensors or flow sensors
Electrical data		
Frequency AC	[Hz]	50...60
Operating voltage	[V]	115...230 AC / 18...30 DC
Current consumption	[mA]	100
Power consumption	[W]	3
Inputs / outputs		
Number of inputs and outputs		Number of analogue inputs: 2; Number of digital outputs: 4; Number of analogue outputs: 1
Inputs		
Number of analogue inputs		2; (Spannungs- oder Stromeingang)
Analogue input (current)	[mA]	0...20
Analogue input (voltage)	[V]	-10...10
Resolution of analogue input		16 bit
Precision analogue input	[%]	0,1
Outputs		
Number of digital outputs		4
Max. current load per output	[mA]	200
Number of analogue outputs		1
Analogue current output	[mA]	0...20
Max. load	[Ω]	270
Analogue voltage output	[V]	-10...10
Precision analogue output	[%]	0,1
Overload protection		yes
Resolution of analogue output		16 bit

DISPLAY/AX460/ANALOG/AC/DC

Connection	
------------	--

