




AS-Interface flat cable insulation displacement connector

FC Splitter AS-i M12 FC top UL

Alternative articles: E75005

When selecting an alternative article and accessories please note that technical data may differ!

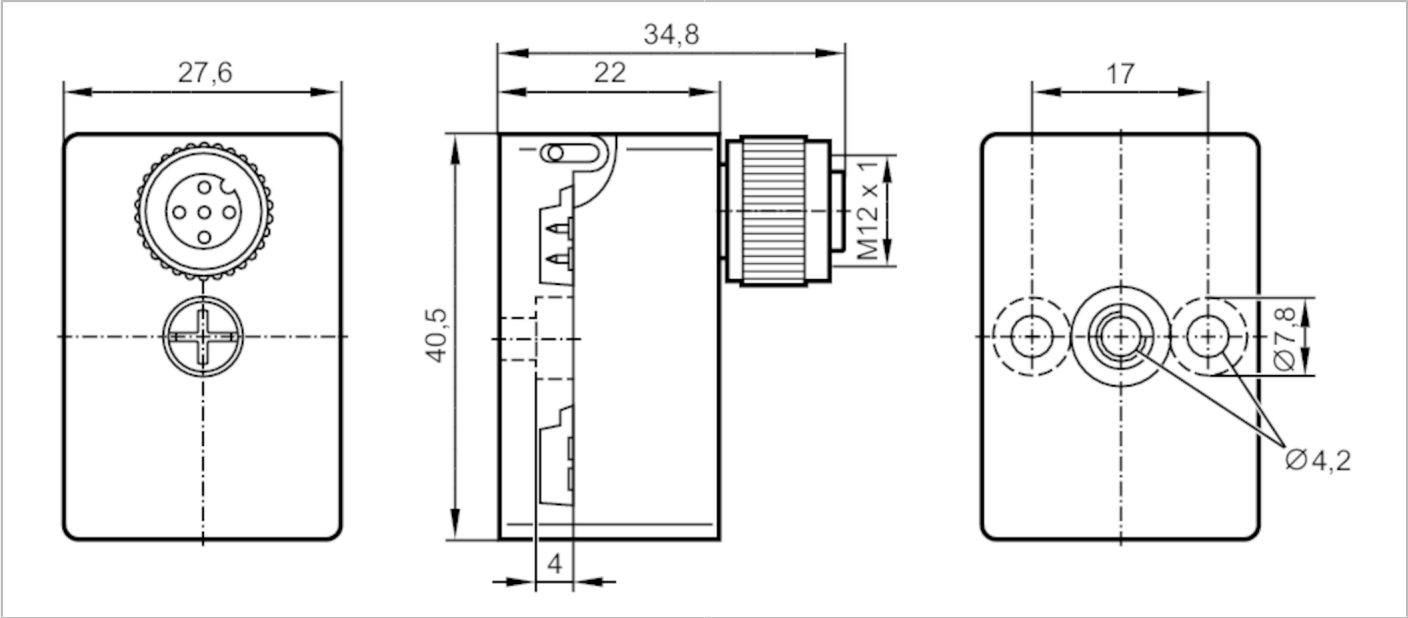

Electrical data		
Protection class		III
Max. current load total	[A]	4
Outputs		
Electrical design		AS-i
Operating conditions		
Ambient temperature	[°C]	-25...75
Protection		IP 67
Mechanical data		
Weight	[g]	53.8
Material		PBT / PC
Tightening torque	[Nm]	1.65
Accessories		
Accessories (optional)		flat cable end seal:, E70413
		Heat-shrink cap:, E70113
Remarks		
Remarks		The flat cable must not end in the splitter.
		Use a flat cable seal or heat-shrink cap for sealing.
		for direct connection of AS-i M8 modules and AS-i CompactModules M12
Pack quantity		1 pcs.




AS-Interface flat cable insulation displacement connector

FC Splitter AS-i M12 FC top UL

Electrical connection

Connector: M12; coding: A

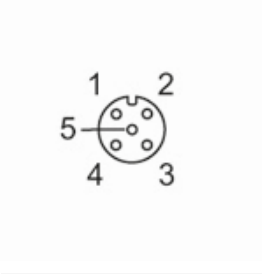

1	AS-i +
3	AS-i -
	Keyway top right