


# E10108



## Female wirable connectors

SDOAH040PLSFKPG

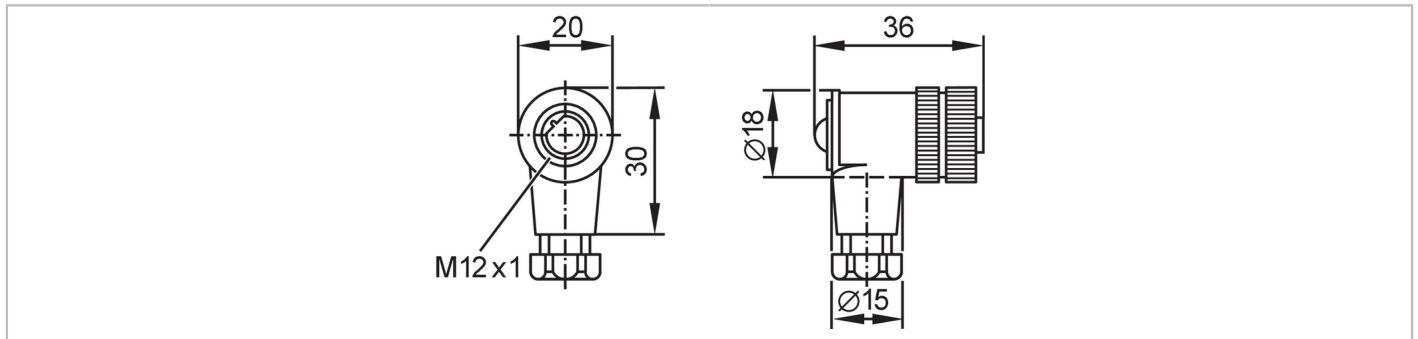

Application		
Application		Industrial applications
Electrical data		
Operating voltage	[V]	< 250 AC/DC
Max. current load total	[A]	4
Operating conditions		
Ambient temperature	[°C]	-40...85
Protection		IP 67
Mechanical data		
Weight	[g]	15.2
Dimensions	[mm]	36 x 20 x 30
Molded-body material		PA
Material nut		PA
Remarks		
Pack quantity		1 pcs.

**Electrical connection**  
 screw terminals: ...0.75 mm<sup>2</sup>; Cable sheath: Ø 4...6 mm; AWG 18

**Electrical connection - Socket**  
 Connector: 1 x M12, angled; coding: B; Contacts: 4, white bronze coated; Moulded body: PA; Locking: PA

