

E11861




Female wirable connectors

SDOGH040VASFKPG

Article no longer available - archive entry

Alternative articles: EVF565

When selecting an alternative article and accessories please note that technical data may differ!

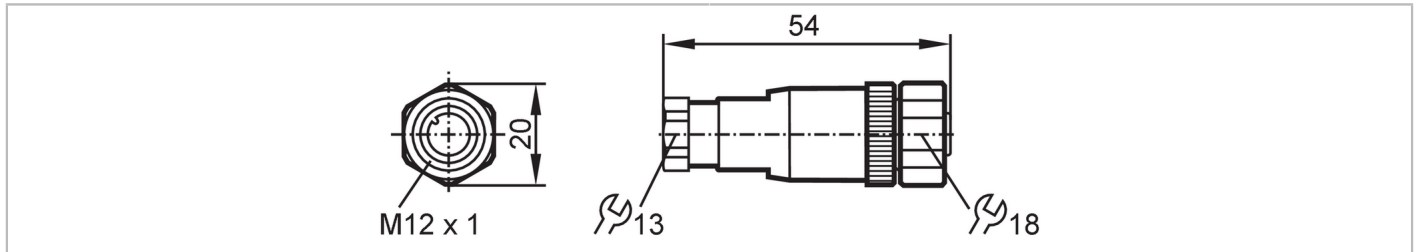

Application

Special feature	Free from silicone; gold-plated contacts
Application	Industrial applications
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 45 AC / < 70 DC
Max. current load total	[A]	4; (...40 °C)

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Weight	[g]	26
Dimensions	[mm]	20 x 20 x 54
Material		PA
Molded-body material		PA
Material nut		stainless steel

Remarks


Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

screw terminals: ...0.75 mm²; Cable sheath: Ø 4...6 mm

Electrical connection - Socket

 Connector: 1 x M12, straight; coding: A; Contacts: 4, gold-plated; Moulded body: PA; Locking: stainless steel; Tightening torque: 0.7...0.9 Nm



E11861



Female wirable connectors

SDOGH040VASFKPG

Connection

