


E11566



T-splitter

T SPLITTER M12/2XUS

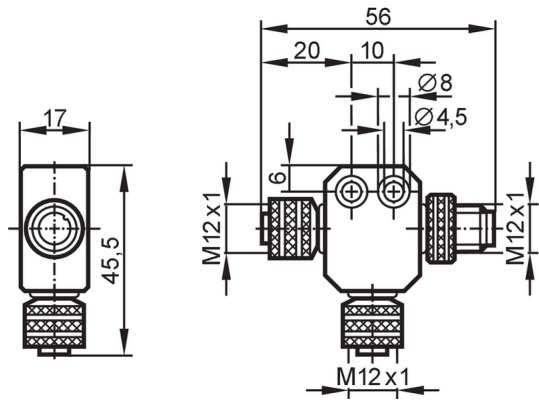

Application

Design	for pressure sensors PNI
Application	Industrial applications

Electrical data

Operating voltage	[V]	< 30 AC / < 36 DC
Max. current load per module/slot	[A]	3
Max. current load total	[A]	3

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Weight	[g]	38.2
Material		housing: PUR

Remarks

Remarks	orientation connectors A/B horizontal (for a vertical sensor)
Pack quantity	1 pcs.



T-splitter


T SPLITTER M12/2XUS

Electrical connection

Connection

AN_i_0711_GG

Original Scale Drawing (MTD)

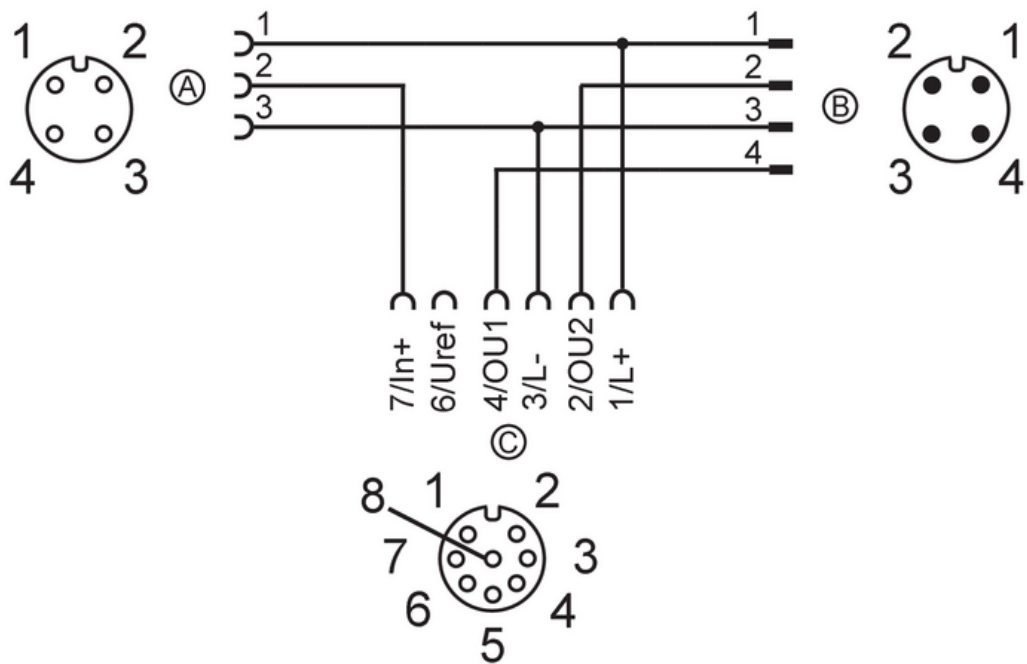

32% 312,5%

EPS Source
Product Scale Drawing
Frame Size: 75 mm x 45 mm

